
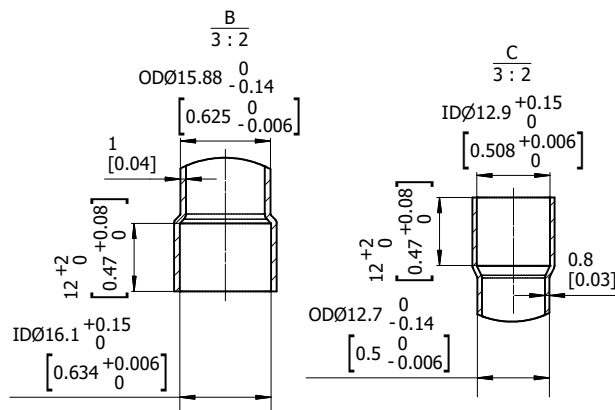
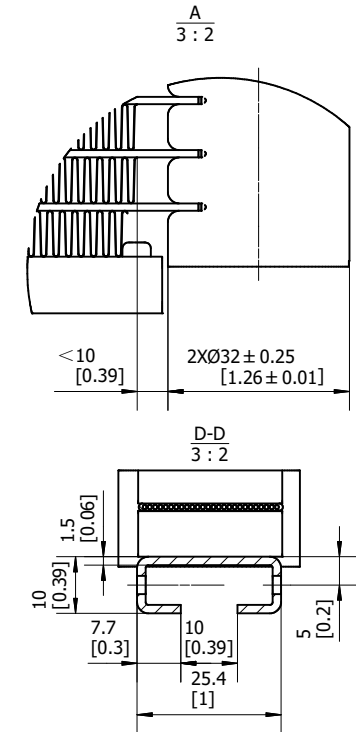


# APPROVED

Name \_\_\_\_\_  
Date \_\_\_\_\_

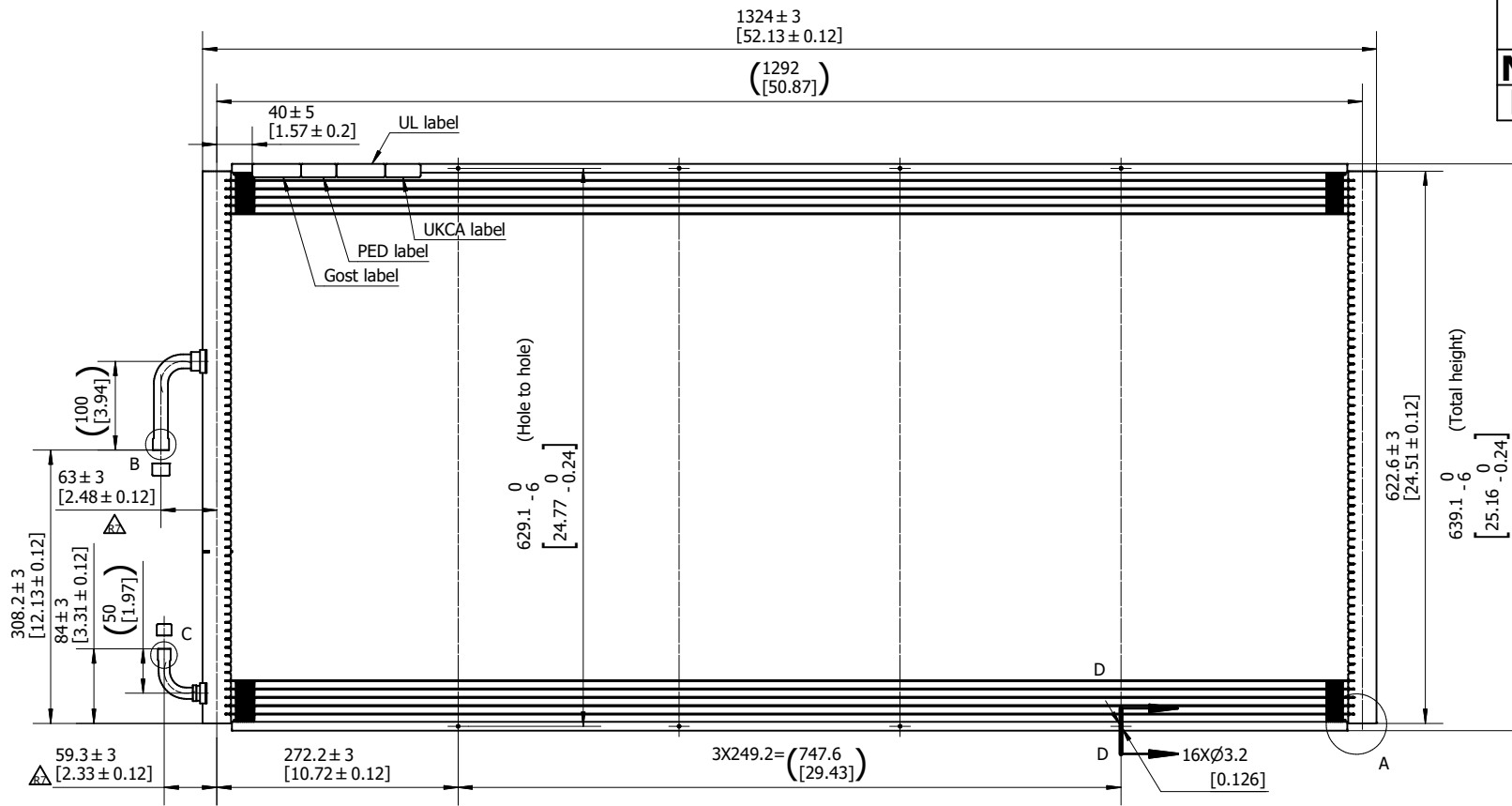

| DISTRIBUTION |    |
|--------------|----|
| IN           | 45 |
| OUT          | 20 |

- △ Technical Specification:
- 1.Product type:C125(25.4S);
  - 2.FPI=23;
  - 3.Tube:25.4X1.3X26ports;
  - 4.Tube material:9153;
  - 5.Inlet and outlet tubes are copper;
  - 6.Internal hold-up volume:1.63L;
  - 7.PS:45bar,TS MIN/MAX:-40°C~121°C.

|     |                                                                   |  |  |  |       |            |                                                                                                                                                                                                           |            |            |          |  |                |                           |                               |             |
|-----|-------------------------------------------------------------------|--|--|--|-------|------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------|------------|----------|--|----------------|---------------------------|-------------------------------|-------------|
| MRK | REVISION RECORD                                                   |  |  |  | DRN   | DATE       | Linear Tolerance Not Specified                                                                                                                                                                            |            |            |          |  | Scale<br>1 : 4 | Size<br>A2                | Angle Tolerance Not Specified |             |
|     | Change transitions to transition blocks and change tube material. |  |  |  | H.JIN | 2023.02.04 | ≤6                                                                                                                                                                                                        | >6-30      | >30-120    | >120-400 |  |                |                           | 0°/90°/180°                   | Other Angle |
|     |                                                                   |  |  |  |       |            | ±0.5                                                                                                                                                                                                      | ±1         | ±1.5       | ±2.5     |  |                | ±3°                       | ±3°                           |             |
|     |                                                                   |  |  |  |       |            | >400-1000                                                                                                                                                                                                 | >1000-2000 | >2000-4000 |          |  |                | Designation               |                               |             |
|     |                                                                   |  |  |  |       |            | ±4                                                                                                                                                                                                        | ±6         | ±8         |          |  |                | MCHE condenser<br>D1700-C |                               |             |
|     |                                                                   |  |  |  |       | DRN        | H.JIN                                                                                                                                                                                                     |            |            |          |  |                |                           |                               |             |
|     |                                                                   |  |  |  |       | APP        |                                                                                                                                                                                                           |            |            |          |  |                |                           |                               |             |
|     |                                                                   |  |  |  |       | DATE       | 2013.08.21                                                                                                                                                                                                |            |            |          |  | Customer PN:   |                           |                               |             |
|     |                                                                   |  |  |  |       |            | Confidential: Property of Danfoss A/S, Nordborg, Denmark.<br>Not to be handed over to, copied or used by third party. Two- or three dimensional reproduction of contents to be authorized by Danfoss A/S. |            |            |          |  |                | NO. X0-DF0091             |                               | REV. 07     |
|     |                                                                   |  |  |  |       |            |                                                                                                                                                                                                           |            |            |          |  |                | WT. 9.865 kg              |                               |             |